


# INSATALLATION INSTRUCTIONS

## RMF-zz-xx/yy

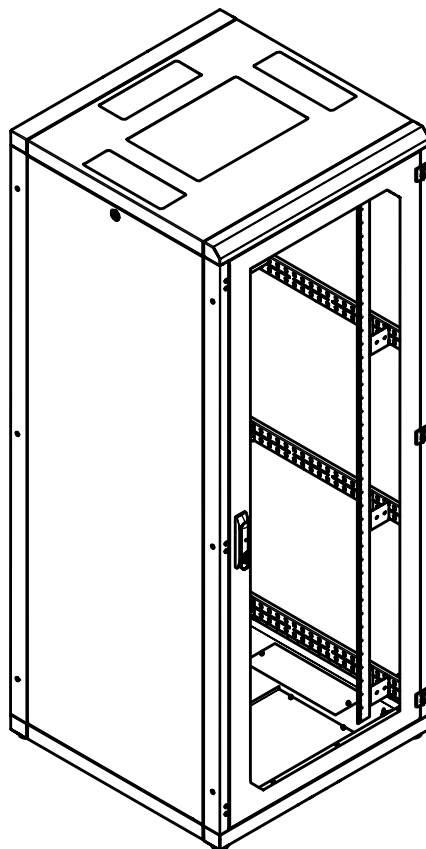







980 128 rev.0




980 128 rev.0


[www.conteg.com](http://www.conteg.com)  
...to complete your network

# 1. Package includes:
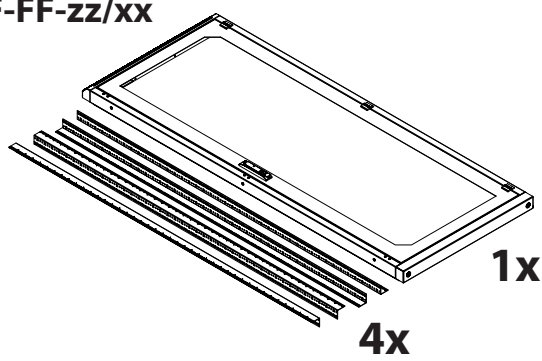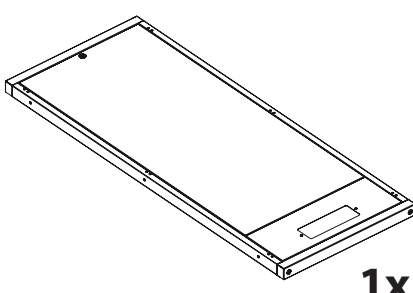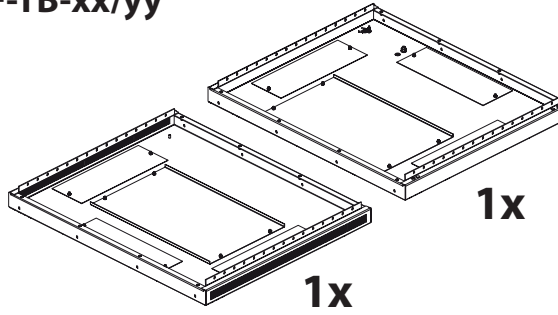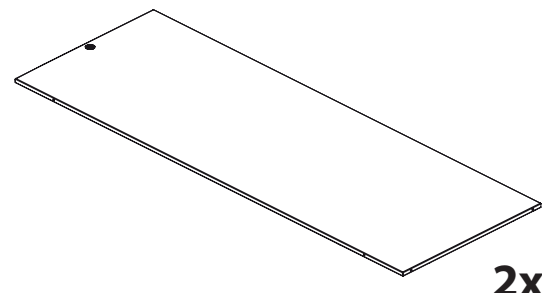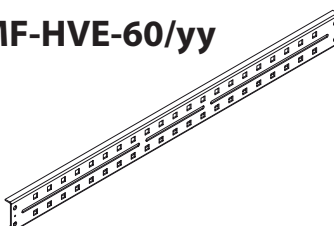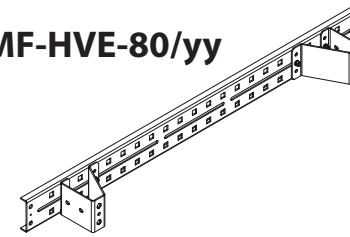
<p><b>RMF-FF-zz/xx</b></p>  <p>1x 4x</p>	<p><b>RMF-RF-zz/xx</b></p>  <p>1x</p>																																																
<p><b>RMF-TB-xx/yy</b></p>  <p>1x 1x</p> <table border="1" data-bbox="127 1030 702 1142"> <tr> <td></td> <td>32x</td> <td>M5x12 ISO 7380</td> <td></td> <td>4x</td> <td>M10x65</td> </tr> <tr> <td></td> <td>3x</td> <td>M5 DIN 985</td> <td></td> <td></td> <td></td> </tr> </table>		32x	M5x12 ISO 7380		4x	M10x65		3x	M5 DIN 985				<p><b>RMF-SP-zz/yy</b></p>  <p>2x</p>																																				
	32x	M5x12 ISO 7380		4x	M10x65																																												
	3x	M5 DIN 985																																															
<p><b>RMF-HVE-60/yy</b></p>  <table border="1" data-bbox="574 1198 774 1355"> <tr><td>RMF-21-60/yy</td><td>4x</td></tr> <tr><td>RMF-33-60/yy</td><td>4x</td></tr> <tr><td>RMF-42-60/yy</td><td>8x</td></tr> <tr><td>RMF-45-60/yy</td><td>8x</td></tr> </table> <table border="1" data-bbox="303 1422 774 1579"> <tr><td></td><td>RMF-21-60/yy</td><td>24x</td><td>M5x10 ISO 7380</td></tr> <tr><td></td><td>RMF-33-60/yy</td><td>24x</td><td>M5x10 ISO 7380</td></tr> <tr><td></td><td>RMF-42-60/yy</td><td>48x</td><td>M5x10 ISO 7380</td></tr> <tr><td></td><td>RMF-45-60/yy</td><td>48x</td><td>M5x10 ISO 7380</td></tr> </table>	RMF-21-60/yy	4x	RMF-33-60/yy	4x	RMF-42-60/yy	8x	RMF-45-60/yy	8x		RMF-21-60/yy	24x	M5x10 ISO 7380		RMF-33-60/yy	24x	M5x10 ISO 7380		RMF-42-60/yy	48x	M5x10 ISO 7380		RMF-45-60/yy	48x	M5x10 ISO 7380	<p><b>RMF-HVE-80/yy</b></p>  <table border="1" data-bbox="1260 1243 1460 1400"> <tr><td>RMF-21-80/yy</td><td>4x</td></tr> <tr><td>RMF-33-80/yy</td><td>4x</td></tr> <tr><td>RMF-42-80/yy</td><td>8x</td></tr> <tr><td>RMF-45-80/yy</td><td>8x</td></tr> </table> <table border="1" data-bbox="981 1422 1460 1579"> <tr><td></td><td>RMF-21-80/yy</td><td>32x</td><td>M5x10 ISO 7380</td></tr> <tr><td></td><td>RMF-33-80/yy</td><td>32x</td><td>M5x10 ISO 7380</td></tr> <tr><td></td><td>RMF-42-80/yy</td><td>64x</td><td>M5x10 ISO 7380</td></tr> <tr><td></td><td>RMF-45-80/yy</td><td>64x</td><td>M5x10 ISO 7380</td></tr> </table>	RMF-21-80/yy	4x	RMF-33-80/yy	4x	RMF-42-80/yy	8x	RMF-45-80/yy	8x		RMF-21-80/yy	32x	M5x10 ISO 7380		RMF-33-80/yy	32x	M5x10 ISO 7380		RMF-42-80/yy	64x	M5x10 ISO 7380		RMF-45-80/yy	64x	M5x10 ISO 7380
RMF-21-60/yy	4x																																																
RMF-33-60/yy	4x																																																
RMF-42-60/yy	8x																																																
RMF-45-60/yy	8x																																																
	RMF-21-60/yy	24x	M5x10 ISO 7380																																														
	RMF-33-60/yy	24x	M5x10 ISO 7380																																														
	RMF-42-60/yy	48x	M5x10 ISO 7380																																														
	RMF-45-60/yy	48x	M5x10 ISO 7380																																														
RMF-21-80/yy	4x																																																
RMF-33-80/yy	4x																																																
RMF-42-80/yy	8x																																																
RMF-45-80/yy	8x																																																
	RMF-21-80/yy	32x	M5x10 ISO 7380																																														
	RMF-33-80/yy	32x	M5x10 ISO 7380																																														
	RMF-42-80/yy	64x	M5x10 ISO 7380																																														
	RMF-45-80/yy	64x	M5x10 ISO 7380																																														

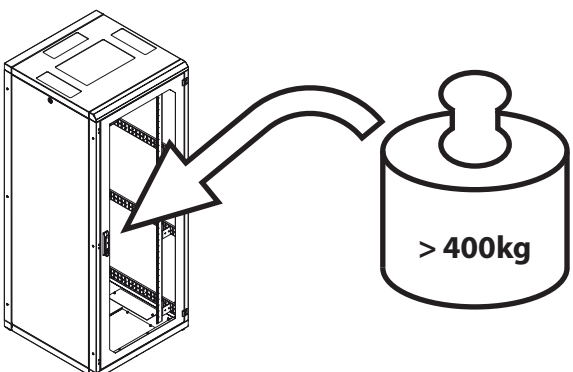

**RMF-BRACE**

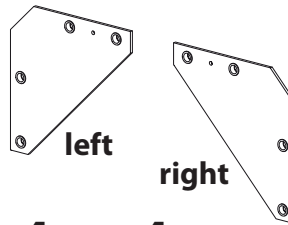

left right


**4x + 4x**

	32x	M5x12 ISO 7380
--	-----	----------------

Required  
Notwendig  
Požadováno  
Demandé  
Требуется



### 1.3 Requested tools (not included)

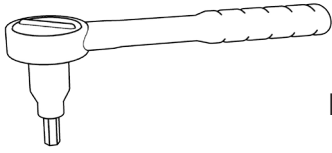

Hex key size 3


### 1.4 Legend




SPIRIT-LEVEL

## 2. Assembly


1.

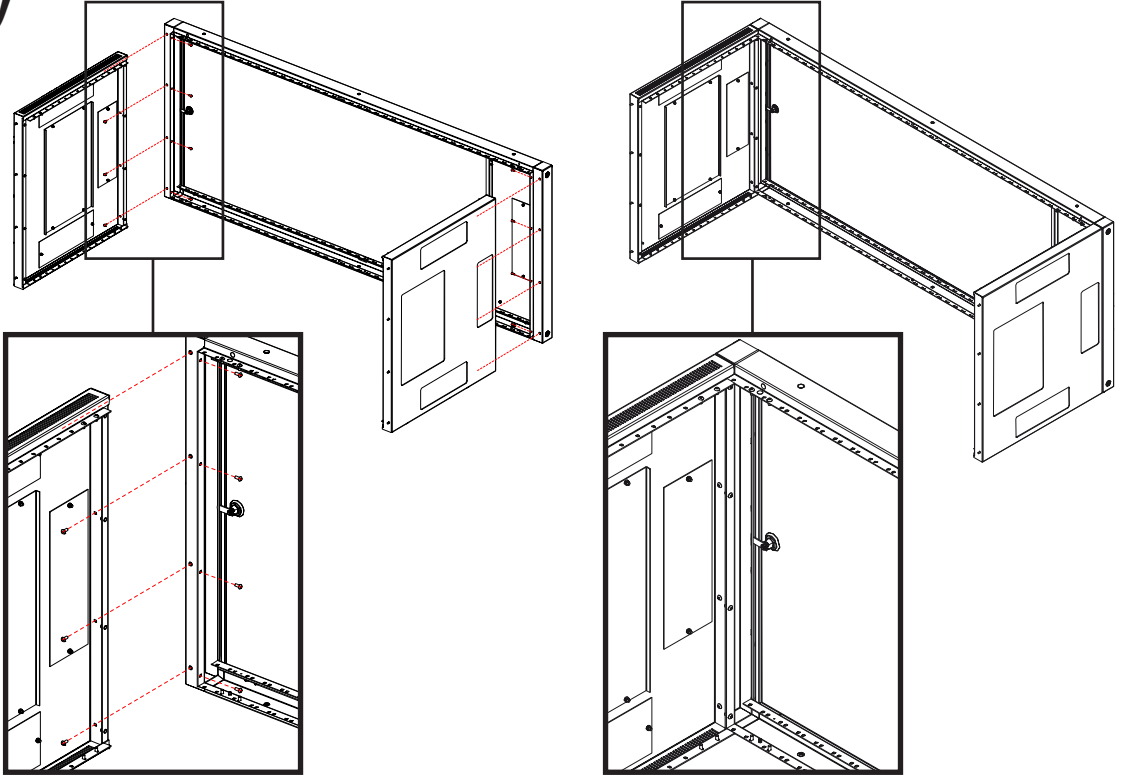




2.

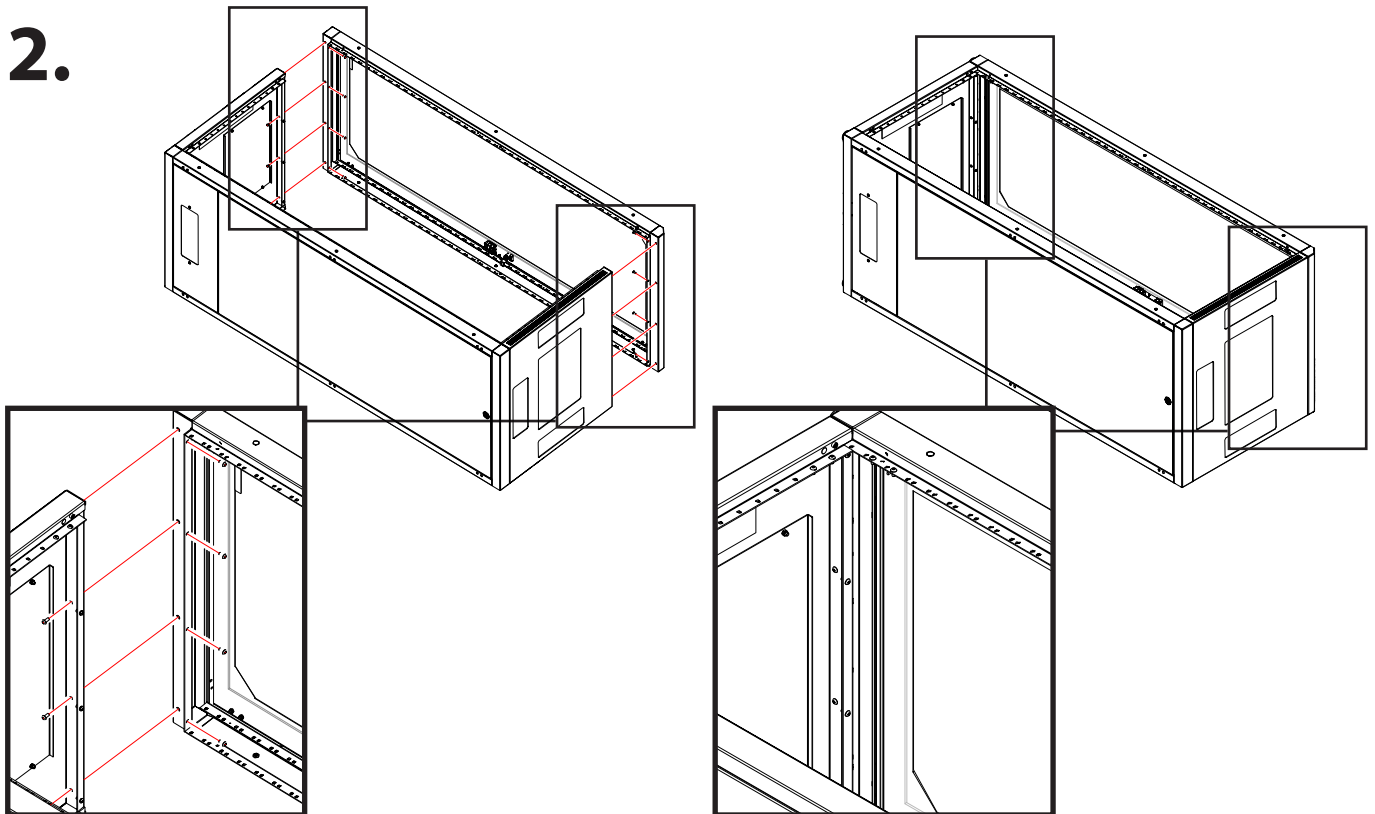


3.

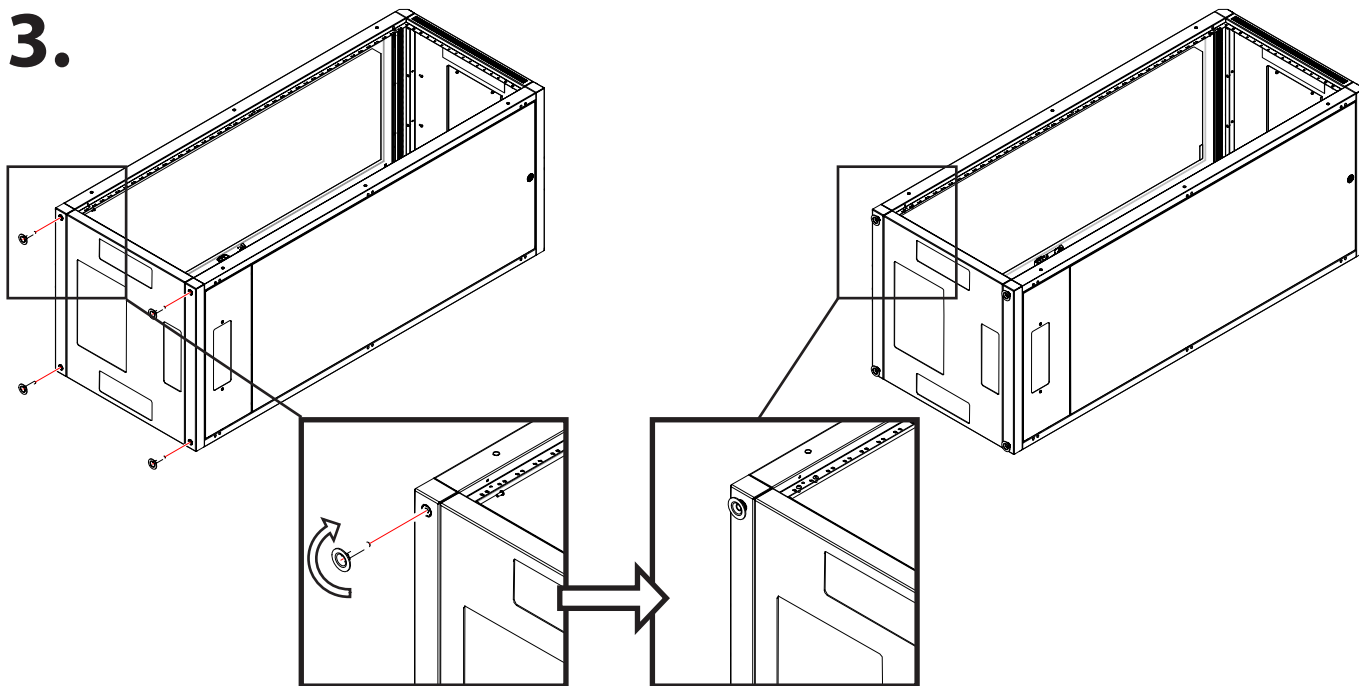


4.

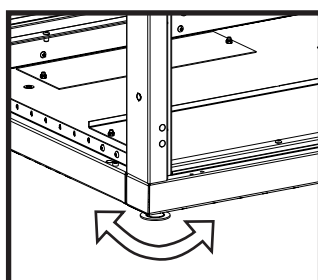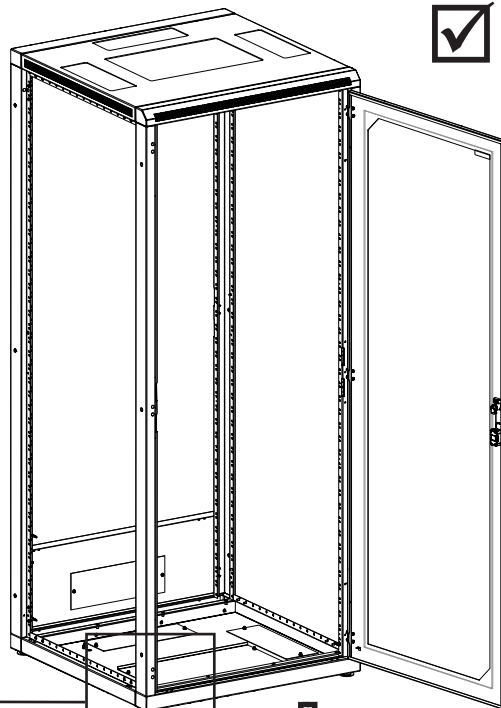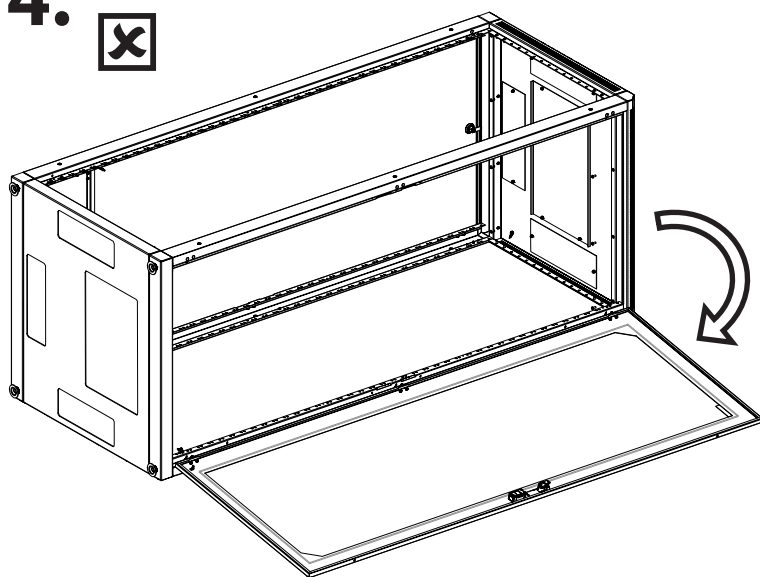


# 5.a - RMF-zz-80/yy

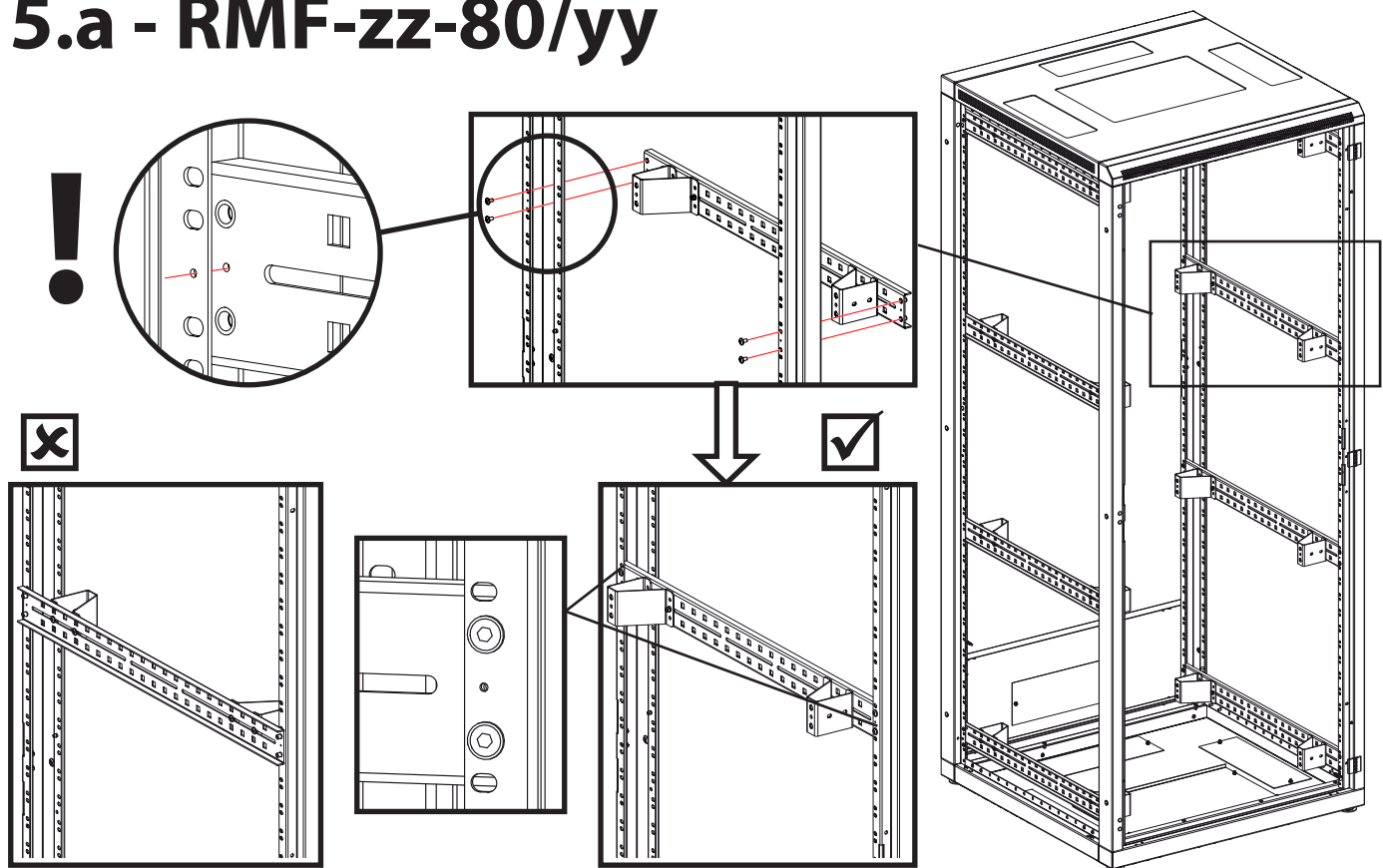


# 5.b - RMF-zz-60/yy

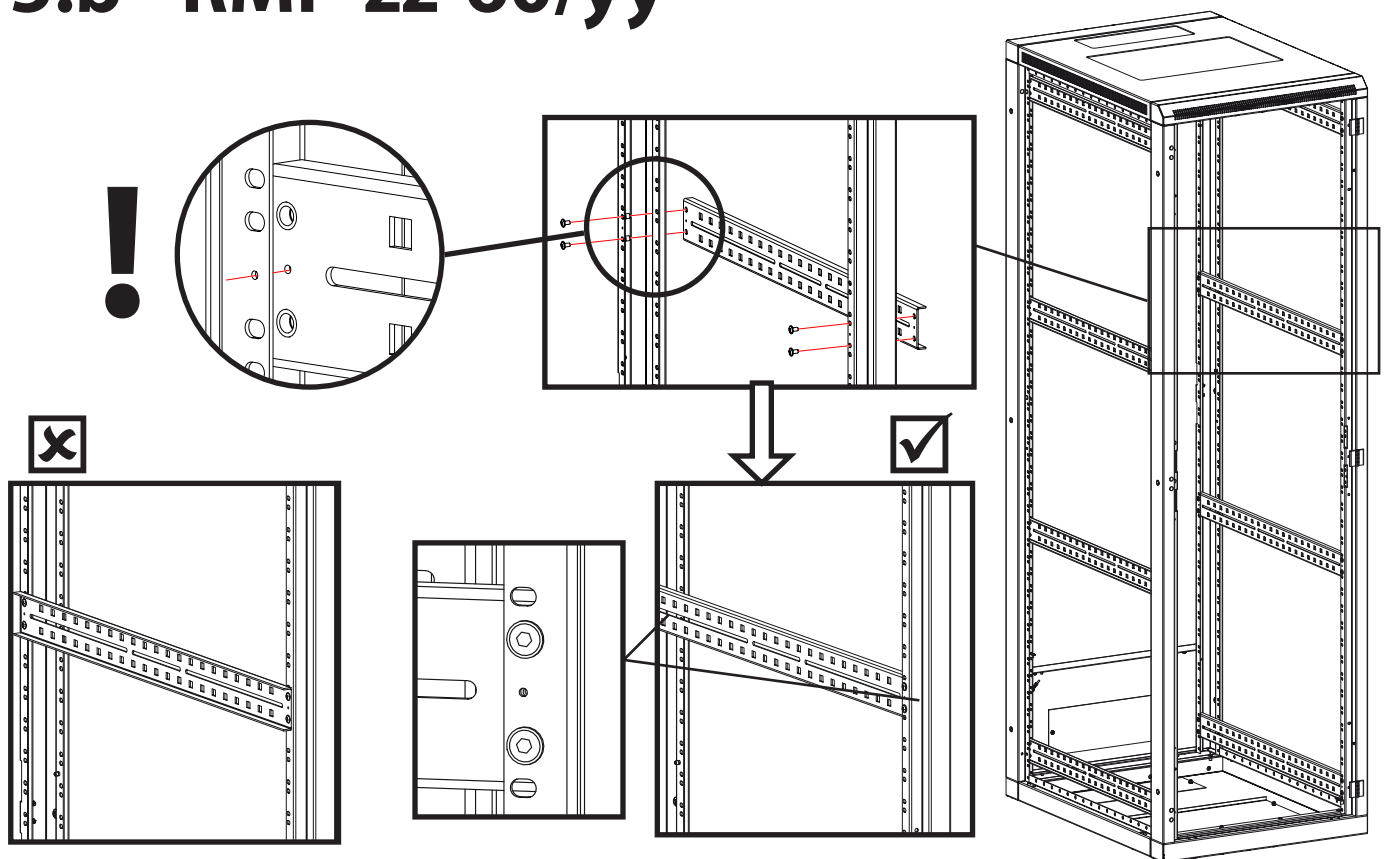




## 6.a - RMF-zz-80/yy

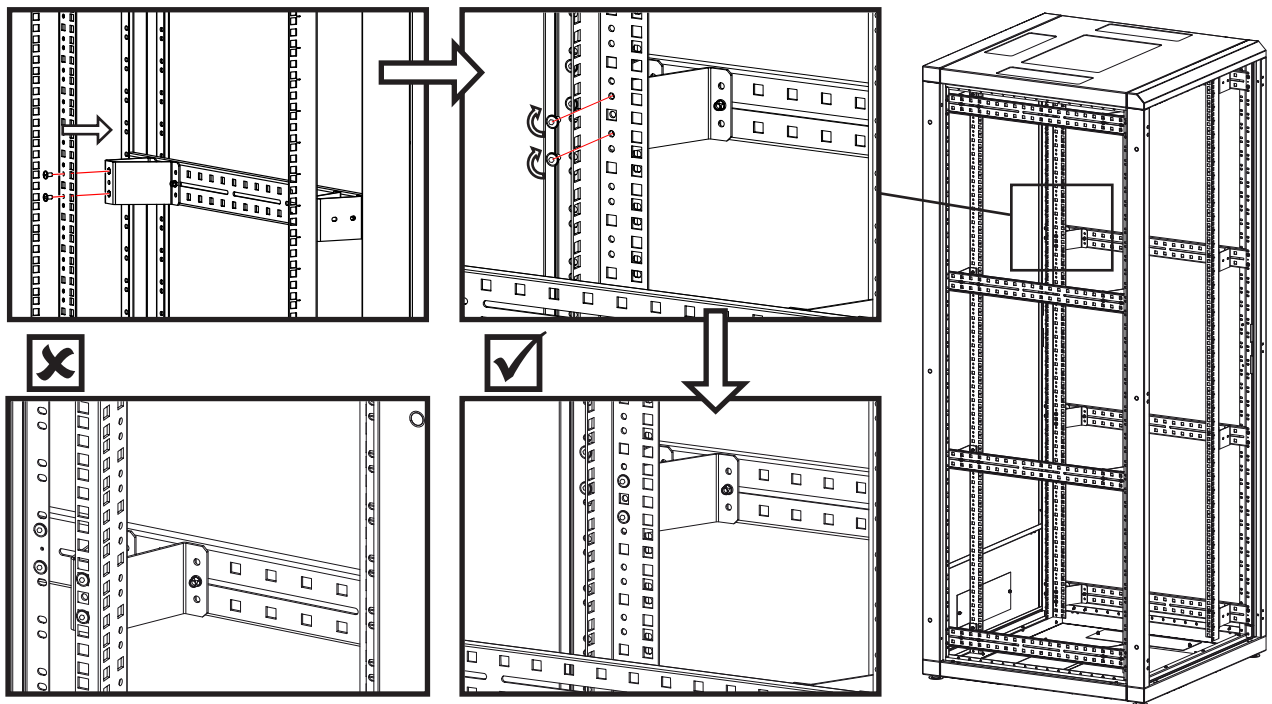


## 6.b - RMF-zz-60/yy

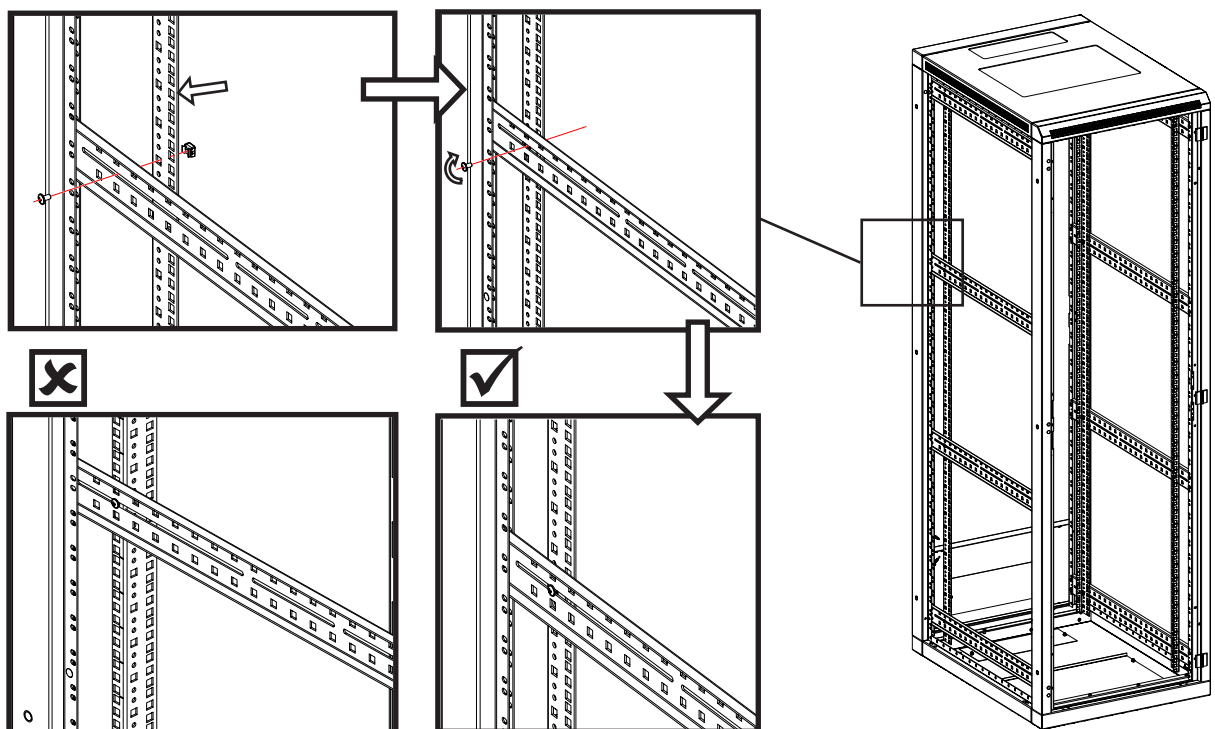


7.

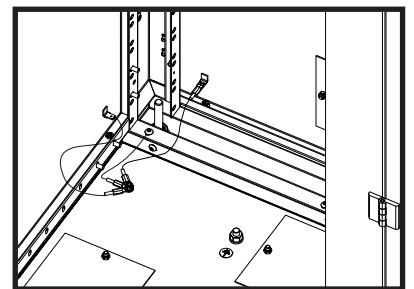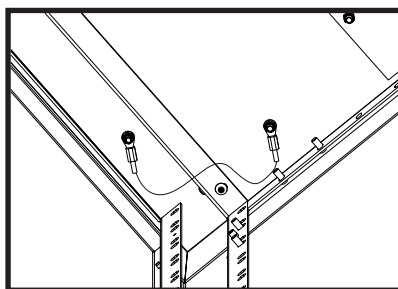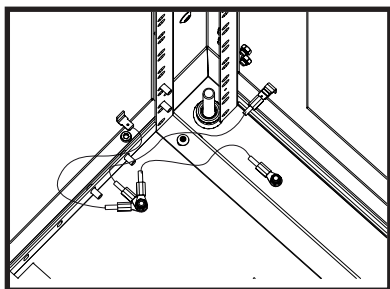


8.

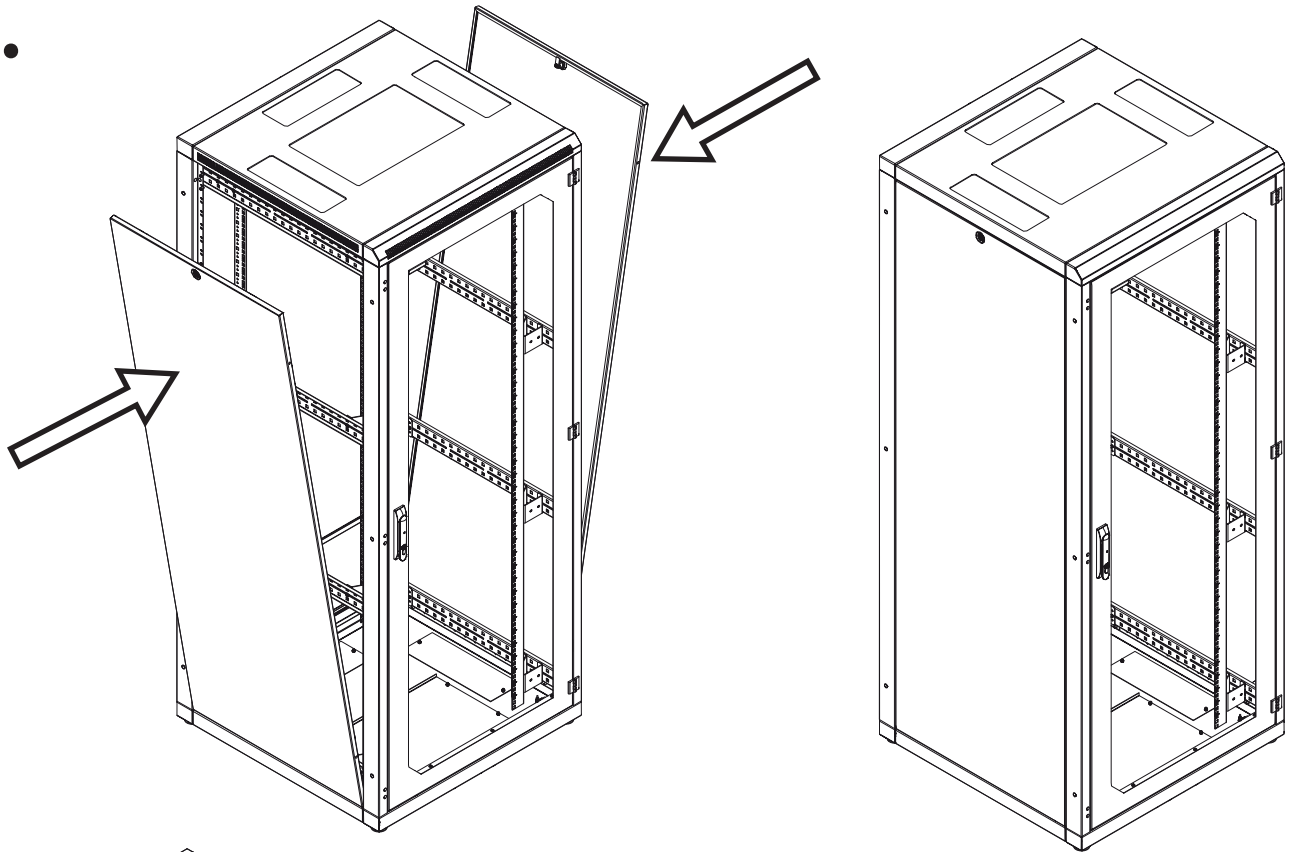

9.

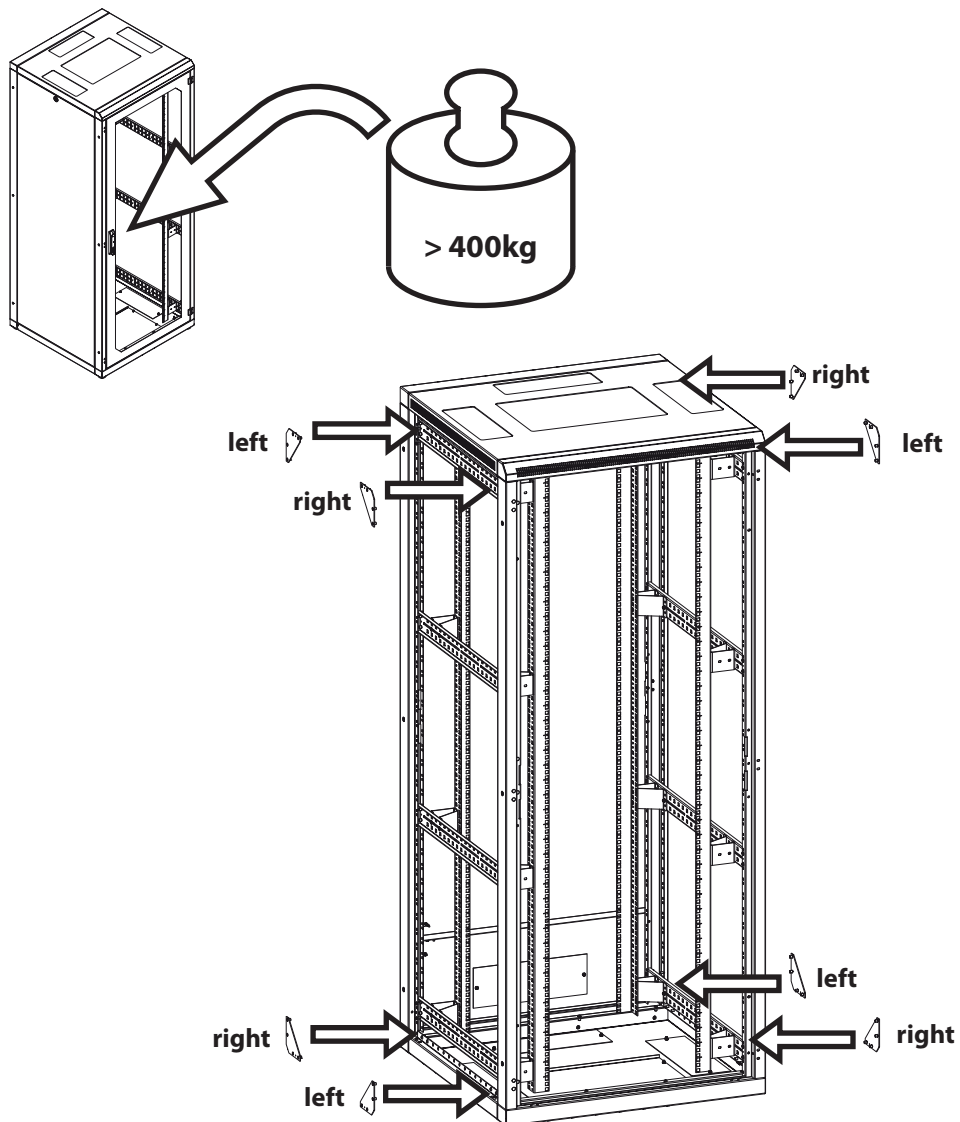



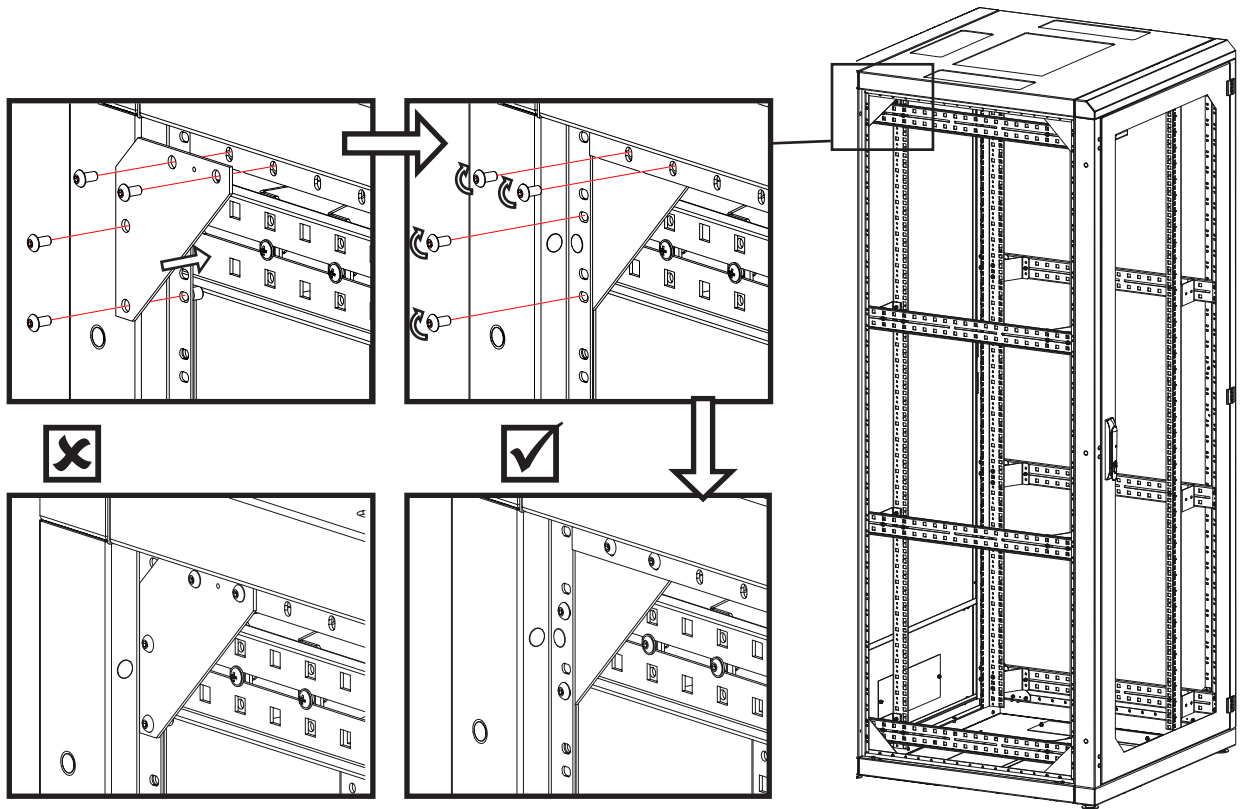

**CONTEG, spol. s r.o.**

**Headquarters Czech Republic:**  
 Na Vítězné pláni 1719/4  
 140 00 Prague 4

Tel.: +420 261 219 182  
 Fax: +420 261 219 192

conteg@conteg.com  
 www.conteg.com

**Local Offices:**

Austria:	+43 699 1819 7071
Benelux:	+32 477 957 126
France:	+33 686 074 386
Germany:	+49 170 523 4958
Russia:	+7 495 967 3840
Slovakia:	+421 917 874 111

