


DATASHEET
Open frames
RSG2

CONTEG

FREE-STANDING RACKS

OPEN FRAMES RSG2

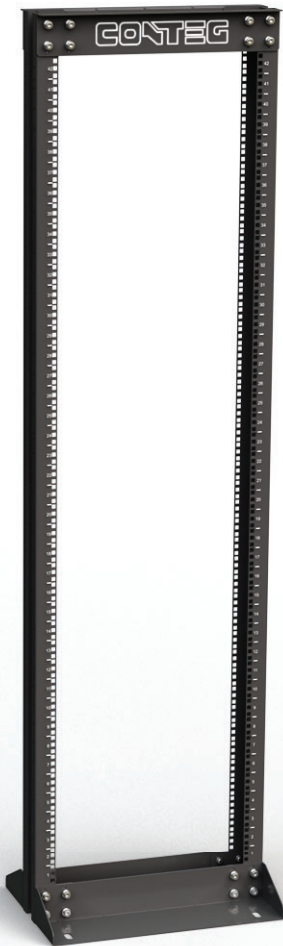

RSG2-42-19-LA





➤ **RSG2** high-load, two post open frames are designed to be used with High Density Wire Management.

MAIN ADVANTAGES

- 2-post frame with 500 or 1000 kg load rating
- Universal frame for cable management (fully compatible with High Density Wire Management)
- Unlimited access to for component installation

Code	H (in U)	H (mm)	Load rating (kg)
RSG2-27-19-L5	27	1388	500
RSG2-42-19-L5	42	2055	500
RSG2-47-19-L5	47	2277	500
RSG2-42-19-LA	42	2055	1000
RSG2-47-19-LA	47	2277	1000

 COLOR:  RAL 9005

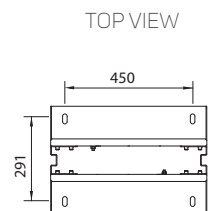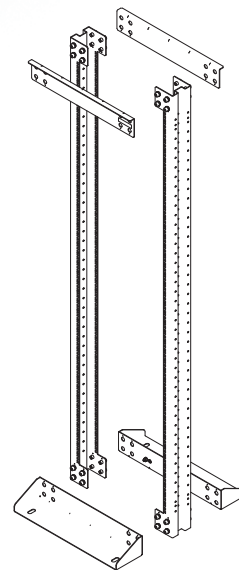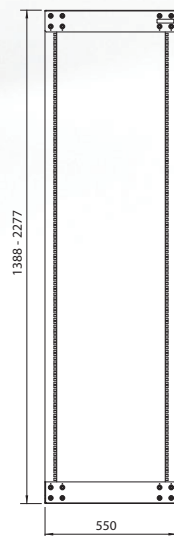

DESCRIPTION:

Sizes

- Height: 27, 42, 47U
- Width: 550 mm
- Depth: 100 mm

Construction

- 2.0 mm sheet steel

Load rating

- 500 kg (balanced load; all heights)
- 1000 kg (balanced load; 42U and 47U only)

IP rating

- IP00 (no protection)

Color

- Standard RAL 9005

Base

- Composed of sheet steel
- Complete with holes for anchoring screws

Standard equipment

- 1 pair of 19" vertical extrusions with U marking
- Top angles
- 2x base

Note: All dimensions in mm



CONTEG, spol. s r.o.

Headquarters:

Na Vitezne plani 1719/4
140 00 Prague 4
Czech Republic

Production plant:

K Silu 2179
393 01 Pelhrimov
Czech Republic

Tel.: +420 565 300 362

conteg@conteg.com

www.conteg.com

CONTEG